


Montageanleitung für konfektionierbare, geschirmte Rundsteckverbinder mit Federzugklemme


- 1 Kabelverschraubung und Gehäuse über das Kabel ziehen
- 2 Kabelmantel und Schirmung um 20 mm bis auf die Adern abisolieren (Schirmgeflecht abschneiden)
- 3 Einzeladern um 10 mm abisolieren
- 4 Äußeren Kabelmantel um 10 mm entfernen. Schirmgeflecht dabei nicht beschädigen!
- 5 Adern anschließen
- 6 Schirmgeflecht mit dem beiliegenden Streifen Schirmfolie umkleben
- 7 Gehäuse mit dem Steckverbinder verschrauben, Kabelverschraubung auf Block festschrauben

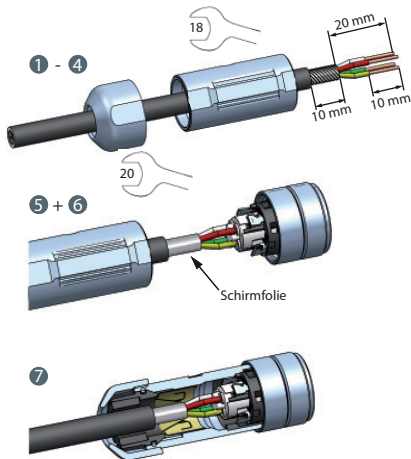

Absetzmaße im Maßstab 1:1

Assembly instructions for field attachable shielded circular connectors with spring-type terminals

- 1 Pull the cable gland and the housing over the cable
- 2 Strip outer jacket and shielding by 20 mm up to the wires (cut off shielding braid)
- 3 Strip individual wires by 10 mm
- 4 Remove external cable jacket by 10 mm. Be careful not to damage the shielding braid
- 5 Connect wires
- 6 Stick the included strip of shielding foil around the shielding braid
- 7 Screw the housing to the connector, tighten the cable gland as far as it will go

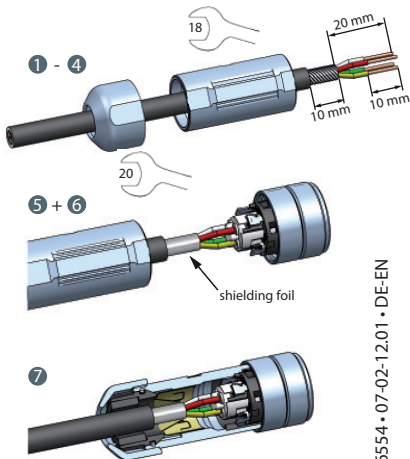

Offset dimensions at a 1:1 scale